


Bellows suction cup VASB-75-1/4-PUR

Part number: 35422

FESTO

With sealing ring OL.

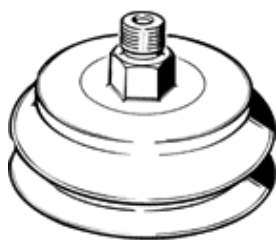

Data sheet

Feature	Value
Nominal size	4 mm
suction cup diameter	75 mm
Effective suction diameter	60 mm
Design structure	Vacuum connection at top round, bellows 1.5 convolutions
Operating medium	Atmospheric air
Ambient temperature	-20 ... 60 °C
Breakaway force at 70% vacuum	197 N
Mounting thread	G1/4
suction cup mounting	G 1/4
Vacuum connection	G1/4
Shore hardness	62
Materials information for screw-in stud	Zinc die-casting
Materials information for suction cup	TPE-U(PU)