


# Barbed L fitting LCNH-M5-PK-2

Part number: 35982

FESTO

Swivelling, with extended housing, for plastic tubing PAN, PUN, PP, PU, PR, with sealing ring.

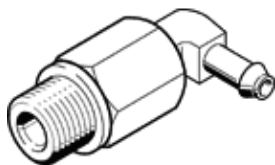

## Data sheet

| Feature                                       | Value   |
|---|---|
| Nominal size                                  | 1.3 mm  |
| Type of seal on screw-in stud                 | Sealing ring  |
| Operating pressure complete temperature range | -0.95 ... 10 bar  |
| Operating medium                              | Compressed air in accordance with ISO8573-1:2010 [7:-:-]                    |
| Note on operating and pilot medium            | Lubricated operation possible (subsequently required for further operation) |
| Corrosion resistance classification CRC       | 2 - Moderate corrosion stress   |
| PWIS conformity                               | VDMA24364-B1/B2-L   |
| Ambient temperature                           | 0 ... 60 °C   |
| Pneumatic connection, port 1                  | Male thread M5  |
| Pneumatic connection, port 2                  | For tubing outside diameter 3 mm  |
| Materials note                                | Conforms to RoHS  |
| Material housing                              | Steel<br>Zinc die-casting   |