 



Bellows cylinder EB-165-65

Part number: 36487

FESTO

Maintenance-free, no stick/slip effect.

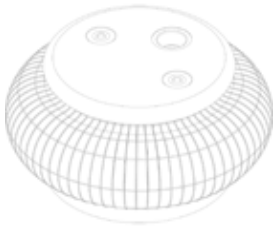

Data sheet

Feature	Value
Size	165
Required installation diameter	180 mm
Stroke	65 mm
Max height when extended	115 mm
Max. tipping angle	20 deg
Max. offset	10 mm
Min. installation height	51 mm
Mode of operation	single-acting
Working pressure	0 ... 8 bar
Operating medium	Compressed air to ISO 8573-1:2010 [-:::4]
Note on operating and pilot medium	Lubricated operation not possible
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-40 ... 70 °C
Reset force	200 N
Product weight	1,200 g
Mounting type	with internal (female) thread
Pneumatic connection	G1/4
Materials note	Conforms to RoHS
Material bellows	NR/BR
Material housing	Steel Galvanized