


# Adaptive Gripper Finger DHAS-GF-120-U-BU

Part number: 3998959

FESTO

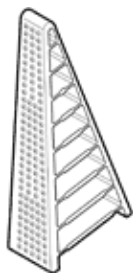

## Data sheet

Feature	Value
Size	120
Assembly position	Any
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
RSBP classification to CD-0033	F1a
Food-safe	See Supplementary material information
Ambient temperature	10 ... 50 °C
Product weight	29 g
Materials note	Conforms to RoHS
Material clamp jaws	TPE-U(PU)