


Coupling plug KS2-CK-3

Part number: 4091

FESTO

For self-closing quick coupling connectors.

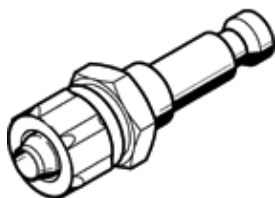

Data sheet

Feature	Value
Nominal size	2 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	68 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	4 g
Pneumatic connection, port 1	CK-3
Materials note	Conforms to RoHS