


Driver DARD-L8-25-S

Part number: 4134871

FESTO

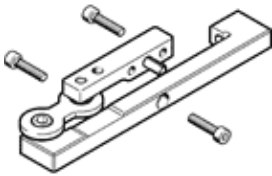

Data sheet

| Feature | Value |
|---|------------------------------------|
| Size | 20/25 |
| Radial deviation +/- | 2.5 mm |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | 0 ... 60 °C |
| Brief maximum permitted load in force direction +/- | 3,000 N |
| Long maximum permitted load in force direction +/- | 1,400 N |
| Product weight | 48 g |
| Materials note | Conforms to RoHS Free of copper |
| Material adapter | Anodised aluminium |
| Material screws | Galvanized steel |