


# Sensor SKDA-0.8-AB

Part number: 4625314

FESTO

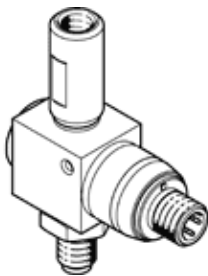

## Data sheet

Feature	Value
Force measuring range	0 ... 0.8 kN
Calibration range	-0.2 ... 1 kN
Limit load	1.5 kN
Operating voltage range DC	10 ... 30 V
Analog output	4 - 20 mA
Accuracy, analog output FS	0.2 %FS
Material housing	Wrought Aluminum alloy High alloy steel, non-corrosive
Materials note	Contains PWIS substances Conforms to RoHS
Product weight	0.2 kg
Ambient temperature	-20 ... 80 °C
Protection class	IP67
Electrical connection	Plug socket M12x1 4-pin A-coded
Corrosion resistance classification CRC	0 - No corrosion stress
CE symbol (see declaration of conformity)	according to EU-EMV guideline in accordance with EU RoHS directive
KC mark	KC-EMV