


# Subbase

## VABS-S7-BE-B-N14-V14-A

Part number: 4727328

FESTO

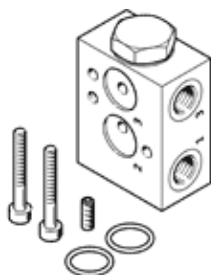

### Data sheet

Feature	Value
Assembly position	Any
Pilot air supply	Internal
Operating pressure MPa	0.2 ... 0.8 MPa
Working pressure	2 ... 8 bar
Flow rate Kv ventilation	2.2 m <sup>3</sup> /h
Flow rate Kv exhaust	8.6 m <sup>3</sup> /h
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:-:-]
Corrosion resistance classification CRC	4 - Very high corrosion stress
PWIS conformity	VDMA24364 zone III
Protection class	IP65
Product weight	250 g
Mounting type	with through hole
Pneumatic connection, port 1	1/4 NPT
Pneumatic connection, port 2	Flange 1/4 NAMUR port pattern
Pneumatic connection, port 3	1/4 NPT
Materials note	Conforms to RoHS
Material of connecting plate	Aluminium (Ematal coated)
Material seals	NBR