


# Round cylinder DGS-16- -P

Part number: 4935  
Product to be discontinued


FESTO

With elastic cushioning rings in end positions

Type to be discontinued. Available until 2016. See Support Portal for alternative products.

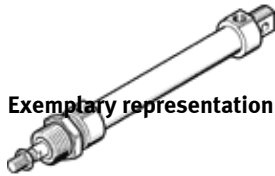

Exemplary representation

 

## Data sheet

Feature	Value
Stroke	1 ... 400 mm
Piston diameter	16 mm
Cushioning	P: Flexible cushioning rings/plates at both ends
Position detection	No
Variants	Single-ended piston rod
Working pressure	1 ... 10 bar
Mode of operation	double-acting
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Ambient temperature	-20 ... 80 °C
Theoretical force at 6 bar, return stroke	91 N
Theoretical force at 6 bar, advance stroke	121 N
Pneumatic connection	G1/8