


# Manifold block MHA4-PR8-3-1/4

Part number: 525237

FESTO

For subbase valves MHA4-...

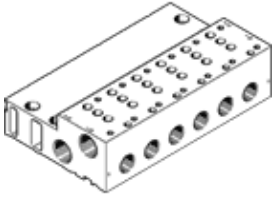

## Data sheet

Feature	Value
Max. number of valve positions	8
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Product weight	1,400 g
Mounting method for subbase	with through hole with top-hat rail
Mounting method for valve	with internal (female) thread
Pneumatic ports 1/33	G3/8
Pneumatic connection, port 2	Female thread 1/4
Pneumatic ports 3/11	G3/8
Material of connecting plate	Wrought Aluminum alloy