

Plastic tubing


PAN-V0-6X1-BL-20

Part number: 525466
Product to be discontinued

FESTO

Flame retardant

Type to be discontinued. Available until 2019. See Support Portal for alternative products.

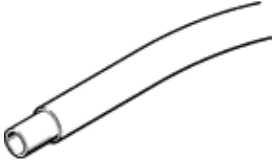

Data sheet

| Feature | Value |
|----------------------------------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Outside diameter | 8 mm |
| Bending radius relevant for flow rate | 30 mm |
| Inside diameter | 4 mm |
| Min. bending radius | 13 mm |
| Temperature dependent working pressure | -0.95 ... 12 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com Mineral oil |
| Material fire test | UL94 V-0 (casing) |
| Ambient temperature | -30 ... 90 °C |
| Product weight according to length | 0.049 kg/m |
| Pneumatic connection | For push-in connector outside diameter 6 mm |
| Color | blue |
| Shore hardness | A 72 +/-4 D 57 +/-3 |
| Materials note | Conforms to RoHS |
| Material tubing | Polyamide 12 PVC-P |