

# Plastic tubing


## PAN-V0-10X1,25-BR-20

Part number: 525488  
Product to be discontinued

FESTO

Flame retardant

Type to be discontinued. Available until 2019. See Support Portal for alternative products.

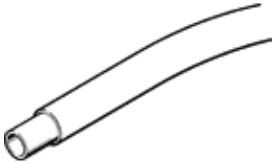

### Data sheet

Feature	Value
Outside diameter	12 mm
Bending radius relevant for flow rate	56 mm
Inside diameter	7.5 mm
Min. bending radius	34 mm
Temperature dependent working pressure	-0.95 ... 12 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at <a href="http://www.festo.com">www.festo.com</a> Mineral oil
Material fire test	UL94 V-0 (casing)
Ambient temperature	-30 ... 90 °C
Product weight according to length	0.088 kg/m
Pneumatic connection	For push-in connector outside diameter 10 mm
Color	brown
Shore hardness	A 72 +/-4 D 57 +/-3
Materials note	Conforms to RoHS
Material tubing	Polyamide 12 PVC-P