


Cable distributor ASI-KVT-FKX2-M12

Part number: 527474

FESTO

For AS interface

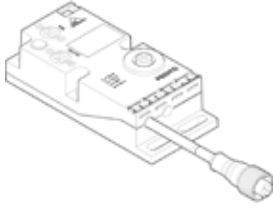

Data sheet

Feature	Value
Width	46 mm
Height	102 mm
Length	28,5 mm
Mounting type	Optional with through hole with top-hat rail
Product weight	190 g
Fieldbus interface	AS interface: flat cable plug bush, M12x1, 4-pin, A-coded Load voltage: flat cable plug
DC operating voltage, AS interface	26.5 ... 31.6 V
Nominal DC operating voltage, AS interface	26.5 V
DC operating voltage, load voltage	20.4 ... 26.4 V
Nominal DC operating voltage, load voltage	24 V
Protection class	IP65 to IEC 60529 in assembled condition
Ambient temperature	-5 ... 50 °C
Storage temperature	-20 ... 70 °C
CE symbol (see declaration of conformity)	according to EU-EMV guideline
Materials note	Conforms to RoHS
Materials information, housing	PA-reinforced
Materials information for seals	PUR
Materials information for cover	PA-reinforced
Relative air humidity	5 - 90 % non-condensing