 



# Clamping unit KEC-25

Part number: 527494

FESTO

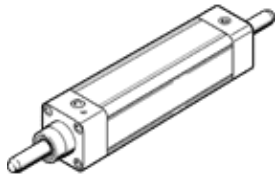

## Data sheet

Feature	Value
Assembly position	Any
Type of clamping with direction of action	at both ends Clamping with spring, release with compressed air
Working pressure	3.8 ... 10 bar
Minimum release pressure	3.8 bar
Round material to be clamped	25 mm
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Corrosion resistance classification CRC	0 - No corrosion stress
Ambient temperature	-20 ... 80 °C
Static holding force	8,000 N
Product weight	16,760 g
Mounting type	with internal (female) thread with accessories
Release connection, clamping unit	G3/8
Materials note	Conforms to RoHS
Material seals	NBR TPE-U(PU)
Material spring	High alloy steel
Material housing	Wrought Aluminum alloy
Material clamp jaws	Tool steel
Material piston	Wrought Aluminum alloy