


coupling socket KD4-CK-9

Part number: 531640

FESTO

Self-closing

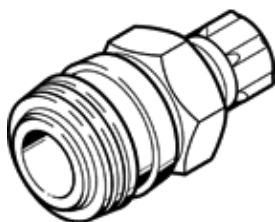

Data sheet

Feature	Value
Nominal size	7.4 mm
Operating pressure complete temperature range	-0.95 ... 12 bar
Standard nominal flow rate	1,017 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	71 g
Pneumatic connection, port 1	CK-9
Materials note	Conforms to RoHS