


Coupling plug KSS6-CK-9

Part number: 531698
Product to be discontinued

FESTO

For self-closing safety coupling per ISO 4414
Type to be discontinued. Available until 2018. See Support Portal for alternative products.

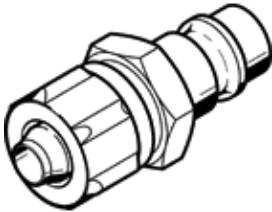

Data sheet

| Feature | Value |
|---|--|
| Nominal size | 7.4 mm |
| Operating pressure complete temperature range | -0.95 ... 12 bar |
| Standard nominal flow rate | 1,269 l/min |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [7:-:-] |
| Note on operating and pilot medium | Lubricated operation possible |
| Corrosion resistance classification CRC | 1 - Low corrosion stress |
| Ambient temperature | -10 ... 60 °C |
| Authorization | BIA TÜV |
| Product weight | 37 g |
| Pneumatic connection, port 1 | CK-9 |
| Materials note | Conforms to RoHS |