 



Fine filter MS4N-LFM-1/4-BRM-Z

Part number: 531811

FESTO

1 µm filter, plastic bowl with plastic bowl guard, manual condensate drain, direction of flow: from right to left.

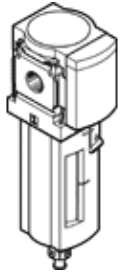

Data sheet

Feature	Value
Size	4
Series	MS
Assembly position	Vertical +/- 5°
Grade of filtration	1 µm
Filter efficiency	99.99 %
Condensate drain	manual rotary
Design structure	Fiber filter
Max. condensate volume	19 ml
Bowl guard	Plastic guard
Inlet pressure 1	0 ... 14 bar
Standard nominal flow rate	180 l/min
Operating medium	Filtered, unlubricated compressed air, 5 µm filtration
Corrosion resistance classification CRC	2
Storage temperature	-10 ... 60 °C
Air purity class at output	2.7.3 per DIN ISO 8573-1
Medium temperature	-10 ... 60 °C
Residual oil content	0.5 mg/m ³
Ambient temperature	-10 ... 60 °C
Product weight	190 g
Mounting type	with accessories Optional Line installation
Pneumatic connection, port 1	NPT1/4-18
Pneumatic connection, port 2	NPT1/4-18
Materials note	Free of copper and PTFE
Materials information for seals	NBR
Materials information for filter	Boron silicate fiber
Materials information, housing	Aluminum die cast
Materials information for bowl	PC