


# Plug base MHAP-PI-1

Part number: 532182

FESTO

For connection blocks and manifold blocks MHA1-P...-PI and MHP1-P...-PI

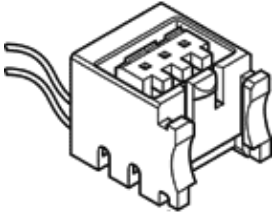

## Data sheet

Feature	Value
Mounting type	Clip
Assembly position	Any
Product weight	6 g
Electrical connection	2-pin Plug socket
Operating voltage range DC	$\leq 60$ V
Permissible current load	3 A
Cable length	1 m
Cable diameter	1 mm
Cable structure	2x0,14
Protection class	IP40
Ambient temperature	-20 ... 80 °C
Ambient temperature with flexible cable installation	-20 ... 50 °C
CE symbol (see declaration of conformity)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material housing	PA
Material electrical contact	Copper alloy, tinned