


Plug FBS-SUB-9-GS-DP-B

Part number: 532216

FESTO

For PROFIBUS

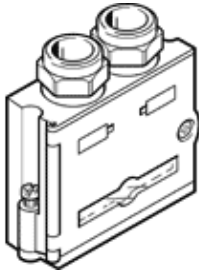

Data sheet

Feature	Value
Width	20 mm
Height	62 mm
Length	61 mm
Protocol	PROFIBUS
Control elements	DIL switches
Additional functions	Switch-off of continued bus segment
Product weight	60 g
Fieldbus interface	2x 2 spring-loaded terminals
Permissible cable diameter	5 ... 10 mm
Protection class	IP65 IP67 in assembled condition to IEC 60529
Ambient temperature	0 ... 50 °C
Storage temperature	-20 ... 70 °C
Relative air humidity	95 % non-condensing
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Material housing	PA-reinforced
Material of union nut	Brass
Material screws	Steel
Material seals	NBR