


Mains outlet socket NTSD-WD-11

Part number: 533119

FESTO

For valve manifolds.

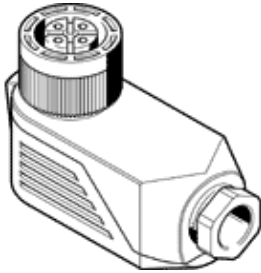

Data sheet

Feature	Value
Mounting type	With sleeve nut
Assembly position	Any
Product weight	34 g
Electrical connection	4-pin Plug socket angled Screwed terminal
Operating voltage range AC	≤ 250 V
Permissible current load	16 A
Cable gland connection	Pg11
Permissible cable diameter	5 ... 11 mm
Terminal cross-section	2.5 mm ²
Protection class	IP67
Ambient temperature	-5 ... 50 °C
Storage temperature	-20 ... 70 °C
PWIS conformity	VDMA24364-B2-L
Material housing	PBT
Material electrical contact	Copper alloy Brass