


Subbase VMPA1-FB-AP-4-1

Part number: 533352

FESTO

For valve manifold MPA-S.

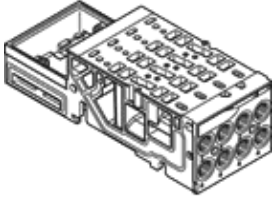

Data sheet

Feature	Value
Width	42 mm
Length	107.3 mm
Grid dimension	10.5 mm
Max. number of valve positions	4
Working pressure	-0.9 ... 10 bar
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	185 g
Pneumatic connection, port 2	M7
Pneumatic connection, port 4	M7
Materials note	Conforms to RoHS
Material of connecting plate	Aluminum die cast