

Plastic tubing


PUN-E-12x1,6-SI-200

Part number: 534178

FESTO

Suitable for use with QS push-in connectors, highly flexible, hydrolysis resistant, micron stable, not approved for use in the production of food products.

Type to be discontinued. Available until 2012.

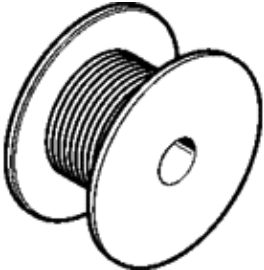

Data sheet

Feature	Value
Outside diameter	12 mm
Bending radius relevant for flow rate	80 mm
Inside diameter	8.8 mm
Min. bending radius	36 mm
Temperature dependent working pressure	-0.95 ... 8 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Ambient temperature	-35 ... 50 °C
Product weight according to length	0.069 kg/m
Color	silver
Shore hardness	D 52 +/-3
Materials note	Free of copper and PTFE Conforms to RoHS
Materials information for tubing	TPE-U(PU)