


Plug FBS-RJ45-8-GS

Part number: 534494

FESTO

For CPX-FEC-... function module

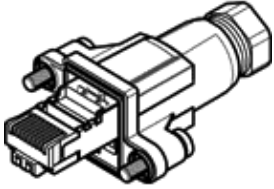

Data sheet

Feature	Value
Width	33 mm
Height	41 mm
Length	20 mm
Product weight	15 g
Ethernet cable specification	Type: CAT 5 Single cable core diameter: 0.89 to 0.99 mm AWG 24-26, finely stranded
Protection against direct and indirect contact	Safety extra-low voltage with safe disconnection (PELV)
Permissible cable diameter	4 ... 5.4 mm
Protection class	IP65 IP67 to IEC 60529
Ambient temperature	-5 ... 60 °C
Storage temperature	-20 ... 70 °C
Relative air humidity	0 - 90 % non-condensing
PWIS conformity	VDMA24364-B2-L
Material housing	PA-reinforced
Material screws	Steel
Material seals	NBR