


# Manifold strip

## VABM-B6-E-G12-10-M1

Part number: 537621

FESTO

for VUVB solenoid valve with multi-pin plug connection.

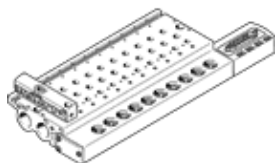

## Data sheet

Feature	Value
Grid dimension	21 mm
Max. number of valve positions	10
Corrosion resistance classification CRC	2
Max. tightening torque, H-rail mounting	1.5 Nm
Max. tightening torque, valve mounting	2 Nm
Max. tightening torque, wall mounting	5 Nm
Product weight	1,380 g
Auxiliary pilot air port 12/14	G1/8
Pneumatic connection, port 1	G1/2
Pneumatic connection, port 3	G1/2
Materials note	Free of copper and PTFE Conforms to RoHS
Material information, manifold strip	Wrought Aluminum alloy