


Subbase VMPA2-IC-AP-1

Part number: 537981

FESTO

for individual valve MPA2 with internal pilot air supply.

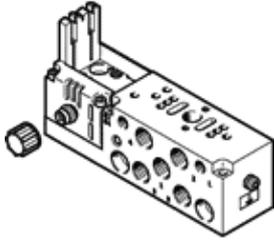

Data sheet

Feature	Value
Width	30.5 mm
Length	107.3 mm
Grid dimension	21 mm
Operating pressure MPa	0.3 ... 0.8 MPa
Working pressure	3 ... 8 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Authorization	c UL us - Recognized (OL)
KC mark	KC-EMV
CE symbol (see declaration of conformity)	according to EU-EMV guideline in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	233 g
Electrical connection	M8 Plug
Mounting method for subbase	with through hole
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 3	G1/8
Pneumatic connection, port 4	G1/8
Pneumatic connection, port 5	G1/8
Materials note	Conforms to RoHS
Material of connecting plate	Aluminum die cast