


Subbase VMPA2-FB-AP-2-1-T0

Part number: 538677

FESTO

For valve manifold MPA-S.

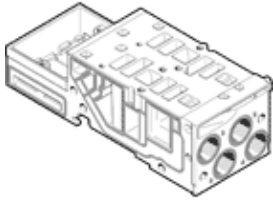

Data sheet

| Feature | Value |
|---|-------------------------|
| Width | 43 mm |
| Length | 107.3 mm |
| Grid dimension | 21 mm |
| Max. number of valve positions | 2 |
| Operating pressure MPa | -0.09 ... 1 MPa |
| Working pressure | -0.9 ... 10 bar |
| Pilot pressure MPa | 0.3 ... 0.8 MPa |
| Pilot pressure | 3 ... 8 bar |
| Corrosion resistance classification CRC | 0 - No corrosion stress |
| PWIS conformity | VDMA24364-B1/B2-L |
| Ambient temperature | -5 ... 50 °C |
| Product weight | 185 g |
| Pneumatic connection, port 2 | G1/8 |
| Pneumatic connection, port 4 | G1/8 |
| Materials note | Conforms to RoHS |
| Material of connecting plate | Aluminum die cast |