 



# Filter silencer LFU-3/8

Part number: 539133

FESTO

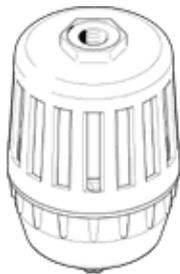

## Data sheet

Feature	Value
Size	G3/8
Assembly position	Vertical +/- 5°
Grade of filtration	1 µm
Condensate drain	manual rotary
Operating pressure MPa	0 ... 1.6 MPa
Working pressure	0 ... 16 bar
Operating pressure	0 ... 232 psi
Flow rate to atmosphere	≥ 4,700 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Noise reduction	Reduction by 40 dB
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Sound pressure level	78 dB(A)
Ambient temperature	-10 ... 60 °C
Product weight	190 g
Pneumatic connection	G3/8
Material housing	PP