


Socket connector MSSD-E-M12

Part number: 539711

FESTO

For solenoid coils and valves, port pattern for JMEH, MEH and MOEH valves.

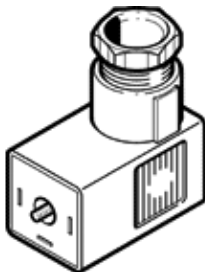

Data sheet

Feature	Value
Connection frequency	50
Mounting type	On solenoid valve with M3 central screw
Assembly position	Any
Product weight	11 g
Electrical connection 1	Angled socket, square design, 3-pin, type C
Electrical connection 2	Screwed terminal
Operating voltage range DC	0 ... 300 V
Operating voltage range AC	0 ... 250 V
Acceptable current load at 40°C	6 A
Cable gland connection	M12
Permissible cable diameter	4 ... 6 mm
Terminal cross-section	0.75 mm ²
Protection class	IP65 to IEC 60529
Ambient temperature	-20 ... 115 °C
PWIS conformity	VDMA24364-B2-L
Materials note	Conforms to RoHS
Degree of contamination	3
Corrosion resistance classification CRC	1 - Low corrosion stress
Material housing	PA-reinforced
Housing color	Black
Material seals	HNBR