


Vertical pressure supply plate

VABF-S4-1-P1A3-G14

Part number: 540171

FESTO

For valve manifolds VTSA and VTSA-F, standard port pattern to 15407-2, for mounting between manifold sub-base and valve.

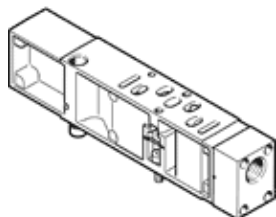

Data sheet

Feature	Value
Width	26 mm
Based on the standard	ISO 15407-2
Assembly position	Any
Operating pressure MPa	1 MPa
Working pressure	10 bar
CE symbol (see declaration of conformity)	according to EU low voltage guideline
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Pilot medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Ambient temperature	-5 ... 50 °C
Product weight	191 g
Vertical stacking type of mounting	on manifold block on individual subbase
Material housing	Aluminum die cast