


# Ball valve actuator unit VZPR-BPD-22-R114

Part number: 540515

FESTO

Brass, with double-acting drive DAPS 2/2-way, nominal width 1 1/4",  
PN40, thread EN 10226-1.

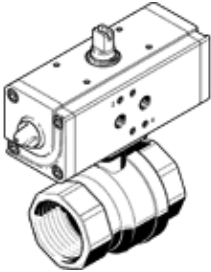

## Data sheet

Feature	Value
Design structure	2-way ball valve Swivel actuator
Type of actuation	electrical pneumatic
Assembly position	Any
Mounting type	CNOMO with internal (female) thread
Process valve connection	Rp1 1/4
Switching position indicator	Knob direction = Flow direction
Nominal diameter DN	32
Working pressure, ball valve actuator	1 ... 8.4 bar
Nominal pressure of process valve	40
Medium temperature	-20 ... 150 °C
Ambient temperature	-20 ... 80 °C
PWIS conformity	VDMA24364 zone III
Product weight	3,200 g
Corrosion resistance classification CRC	1 - Low corrosion stress