


Solenoid coil

VACN-N-K11-1-0.5-U4-M

Part number: 541665

FESTO

Cable with insulating conduit connection, 24 V DC

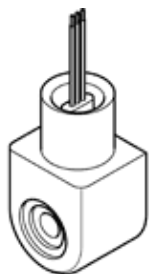

Data sheet

Feature	Value
Characteristic coil data	24 V DC: 4.5 W
Permissible voltage fluctuation	+/- 10 %
Explosion protection certification outside the EU	NEC 500 Class I, Div. 1
Corrosion resistance classification CRC	1
Protection class	IP65
Ambient temperature	-20 ... 60 °C
Cable length	0.5 m
Materials note	Conforms to RoHS