 



Branching module MS12N-FRM-G

Part number: 541682

FESTO

To distribute compressed air without non-return function.

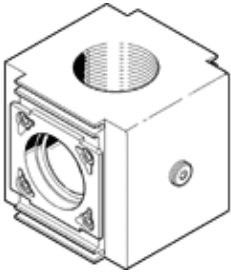

Data sheet

Feature	Value
Assembly position	Any
Design structure	Branching module
Working pressure	0 ... 20 bar
Standard nominal flow rate in main flow direction 1->2	25,000 ... 42,000 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-::-]
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B2-L
Storage temperature	-10 ... 60 °C
Medium temperature	-10 ... 60 °C
Ambient temperature	-10 ... 60 °C
Product weight	3,000 g
Pneumatic connection, port 1	Manifold module
Pneumatic connection, port 2	Manifold module
Pneumatic connection, port 3	2 NPT
Pneumatic connection, port 4	1 NPT
Material housing	Aluminum die cast