


# Intermediate-position module DADM-DGC-25-A

Part number: 541700

FESTO

For DGC and DGCI linear drives.

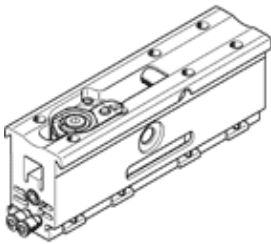

## Data sheet

Feature	Value
Size	25
Assembly position	Any
Position detection	For proximity sensor
Operating pressure MPa	0.25 ... 0.8 MPa
Working pressure	2.5 ... 8 bar
Operating pressure	36.25 ... 116 psi
Max. impact speed	3 m/s
Max. swivel time	100 ms
Repetition accuracy	0.02 mm
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	430 g
Mounting type	Clamped to cylinder DGC
Pneumatic connection	QS-4
Materials note	Conforms to RoHS
Material stop screw	Steel Galvanized
Material seals	NBR
Material housing	Wrought Aluminum alloy Anodized
Material lever	High alloy steel, non-corrosive
Material clip	High alloy steel, non-corrosive
Material nut	Steel Galvanized
Precision adjustment	2 mm
Mode of operation	double-acting