


# Intermediate-position module DADM-DGC-40-A

Part number: 541702

FESTO

suitable for linear actuator DGC.

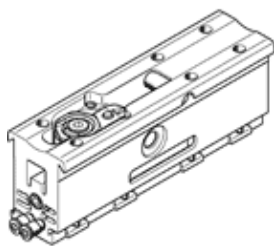

## Data sheet

Feature	Value
Size	40
Assembly position	Any
Position detection	For proximity sensor
Operating pressure MPa	0.25 ... 0.8 MPa
Working pressure	2.5 ... 8 bar
Operating pressure	36.25 ... 116 psi
Max. impact speed	3 m/s
Max. swivel time	300 ms
Repetition accuracy	0.02 mm
Corrosion resistance classification CRC	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 ... 60 °C
Product weight	970 g
Mounting type	Clamped to cylinder DGC
Pneumatic connection	M5
Materials note	Conforms to RoHS
Material stop screw	Steel Galvanized
Material seals	TPE-U(PU)
Material housing	Wrought Aluminum alloy Anodized
Material lever	High alloy steel, non-corrosive
Material clip	High alloy steel, non-corrosive
Material nut	Steel Galvanized
Precision adjustment	4 mm
Mode of operation	double-acting