


# Power supply unit SVG-1/230VAC-48VDC-5A

Part number: 542403  
Product to be discontinued

FESTO

With 48 V DC rated output voltage and 5 A rated output current.  
Type to be discontinued. Available until 2014. See Support Portal for alternative products.

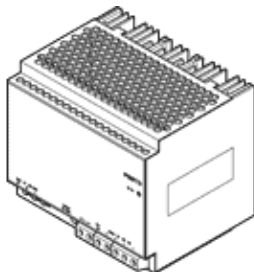

## Data sheet

Feature	Value
Width	125 mm
Height	130 mm
Length	85 mm
Assembly position	Free convection
Primary supply	Single-phase
Input current	2,2 - 1,2 A
Nominal output voltage DC	48 V
Nominal output current	5 A
Input voltage range AC	100 ... 240 V
Power failure buffering	50 ms
Line frequency	45 ... 65 Hz
CE symbol (see declaration of conformity)	according to EU-EMV guideline according to EU low voltage guideline
Storage temperature	-40 ... 85 °C
Relative air humidity	95%
Protection class	IP20
Ambient temperature	-25 ... 70 °C
Authorization	C-Tick c UL us - Listed (OL)
Product weight	1,240 g
Mounting type	with top-hat rail
Materials note	Contains PWIS substances