

 

# Vertical pressure isolating plate

## VABF-S4-2-L1D1-C

Part number: 542884

FESTO

For valve manifolds VTSA and VTSA-F, standard port pattern to 15407-2, for mounting between manifold sub-base and valve, supply pressure of the manifold is blocked. Dismantling of the valve is possible without shutting off the pressure of the manifold.

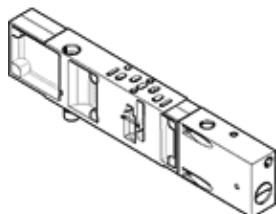

## Data sheet

Feature	Value
Width	18 mm
Based on the standard	ISO 15407-2
Assembly position	Any
Operating pressure MPa	1 MPa
Working pressure	10 bar
CE symbol (see declaration of conformity)	according to EU low voltage guideline
UKCA marking (see declaration of conformity)	To UK instructions for electrical equipment
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Pilot medium	Compressed air in accordance with ISO8573-1:2010 [7:4:4]
Ambient temperature	-5 ... 50 °C
Product weight	209 g
Vertical stacking type of mounting	on manifold block on individual subbase
Material housing	Aluminum die cast