


Parallel kit EAMM-U-D40-55A

Part number: 543157

FESTO

Suitable for electric drives.

Type to be discontinued. Available until 2023. See Support Portal for alternative products.

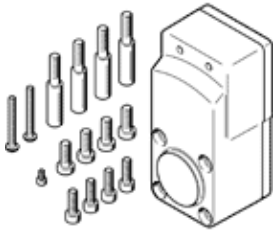

Data sheet

Feature	Value
Size	40
Assembly position	Any
Max. speed	5,000 1/min
PWIS conformity	VDMA24364 zone III
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	0 ... 50 °C
Mass moment of inertia	10.016 kgmm ²
No-load driving torque	0.1 Nm
Transferable torque	3 Nm
Product weight	530 g