


Parallel kit EAMM-U-E32-42B

Part number: 543228

FESTO

Suitable for electric drives.

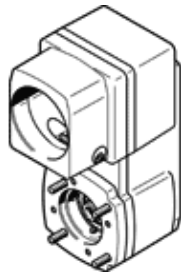

Data sheet

Feature	Value
Size	25
Assembly position	Any
Max. speed	3,000 1/min
Storage temperature	-25 ... 60 °C
Relative air humidity	0 - 95 %
Protection class	IP40
Ambient temperature	0 ... 50 °C
Mass moment of inertia	10.22 kgmm ²
No-load driving torque	0.1 Nm
Transferable torque	3 Nm
Product weight	660 g
Materials note	Contains PWIS substances