


Connector KVI-CP-3-SSD

Part number: 543252

FESTO

to control cabinet through-hole.

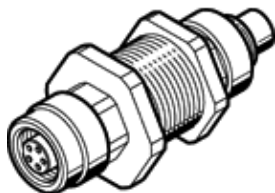

Data sheet

Feature	Value
Mounting type	with external (male) thread
Product weight	48 g
Electrical connection	5-pin Plug socket Straight socket / straight plug M9 Plug
Operating voltage range DC	60 V
Protection class	IP65 IP67
Ambient temperature	-20 ... 80 °C
PWIS conformity	VDMA24364-B2-L
Corrosion resistance classification CRC	2 - Moderate corrosion stress
Material housing	Brass Nickel plated
Material seals	NBR
Assembly position	Any