


# Multi-pin node VABE-S6-1LF-C-M1-R19

Part number: 543415

FESTO

For valve manifolds VTSA and VTSA-F.

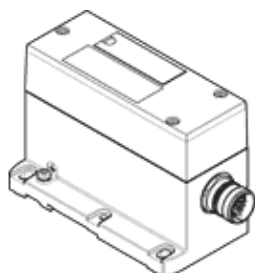

## Data sheet

Feature	Value
Assembly position	Any
Max. number of valve positions	16 with monostable valves 8 with bistable valves
Nominal operating voltage DC	24 V
Permissible voltage fluctuation	+/- 10 %
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Ambient temperature	-5 ... 50 °C
Product weight	539 g
Electrical connection	Multi-pin plug 19-pin Plug To CNOMO E03.62.530.N
Material cover	PA
Material housing	Aluminum die cast