 



Push-in T connector NEDU-M8D3-M8T4

Part number: 544391

FESTO

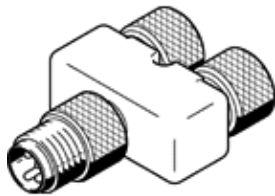

Data sheet

| Feature | Value |
|---|--|
| Assembly position | Any |
| Connection frequency | 100 |
| Operating voltage range AC | 32 V |
| Operating voltage range DC | 32 V |
| Nominal operating voltage, AC | 32 V |
| Nominal operating voltage DC | 32 V |
| Permissible current load | 2 A |
| Corrosion resistance classification CRC | 2 |
| Storage temperature | -25 ... 85 °C |
| Protection class | IP65 IP67 |
| Ambient temperature | -25 ... 85 °C |
| Max. tightening torque | 0.3 Nm |
| Product weight | 9.5 g |
| Electrical connection | to EN 60947-5-2 Plug/socket M8x1 / M8x1 4-pin / 3-pin |
| Mounting type | Threaded |
| Housing color | Black |
| Materials information for locknut | Brass Chromed-plated Nickel plated |
| Materials note | Free of copper and PTFE |
| Materials information, housing | PA |
| Material information for crimp connectors | Brass Gold plated |