


Manifold strip VABM-B6-E-G12-11

Part number: 545824

FESTO

For VUVB solenoid valves.

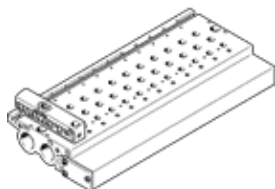

Data sheet

| Feature | Value |
|---|---|
| Grid dimension | 21 mm |
| Max. number of valve positions | 11 |
| Corrosion resistance classification CRC | 2 |
| Max. tightening torque, H-rail mounting | 1.5 Nm |
| Max. tightening torque, valve mounting | 2 Nm |
| Max. tightening torque, wall mounting | 5 Nm |
| Product weight | 1,500 g |
| Auxiliary pilot air port 12/14 | G1/8 |
| Pneumatic connection, port 1 | G1/2 |
| Pneumatic connection, port 3 | G1/2 |
| Materials note | Free of copper and PTFE Conforms to RoHS |
| Material information, manifold strip | Wrought Aluminum alloy |