


# Subbase VMPA2-AP-2-1-EMM-4

Part number: 546805

FESTO

For valve manifold MPA-S.

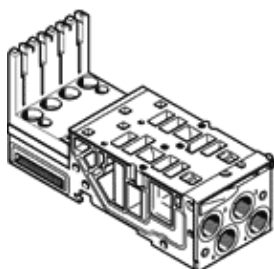

## Data sheet

Feature	Value
Width	42 mm
Length	107.3 mm
Grid dimension	21 mm
Max. number of valve positions	2
Operating pressure MPa	-0.09 ... 1 MPa
Working pressure	-0.9 ... 10 bar
Pilot pressure MPa	0.3 ... 0.8 MPa
Pilot pressure	3 ... 8 bar
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 ... 50 °C
Product weight	210 g
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 4	G1/8
Materials note	Conforms to RoHS
Material of connecting plate	Aluminum die cast