

T fitting


NPFB-T-2R14-G14-MMF

Part number: 547776

FESTO

For connection with pipes.

When using R and G threaded lugs, thread sealing tape or liquid sealant is recommended as an additional sealing material. For sealing the G threaded lug, an axial sealing ring of soft aluminum AL 99.5 can also be used.

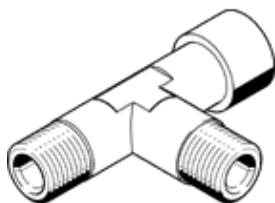

Data sheet

| Feature | Value |
|---|---|
| Material information for threaded fitting | Brass Nickel plated |
| Container size | 10 |
| Working pressure | -0.95 ... 40 bar |
| Operating medium | Compressed air in accordance with ISO8573-1:2010 [-:~:] |
| Corrosion resistance classification CRC | 1 |
| Ambient temperature | -20 ... 150 °C |
| Product weight | 43 g |
| Pneumatic connection, port 1 | R1/4 |
| Pneumatic connection, port 2 | G1/4 |
| Materials note | Conforms to RoHS |