


# Double nipple NPFB-D-R18-R14-M

Part number: 547788

FESTO

For connection with pipes.

When using R and G threaded lugs, thread sealing tape or liquid sealant is recommended as an additional sealing material. For sealing the G threaded lug, an axial sealing ring of soft aluminum AL 99.5 can also be used.

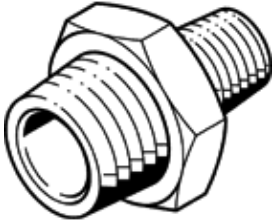

## Data sheet

Feature	Value
Material information for threaded fitting	Brass Nickel plated
Container size	10
Working pressure	-0.95 ... 40 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [-:::]
Corrosion resistance classification CRC	1
Ambient temperature	-20 ... 150 °C
Product weight	17 g
Pneumatic connection, port 1	R1/8
Pneumatic connection, port 2	R1/4
Materials note	Conforms to RoHS