


Power supply unit SVG-1/230VAC-ASI-5A

Part number: 547869

Product to be discontinued

FESTO

Type to be discontinued. Available until 2017. See Support Portal for alternative products.

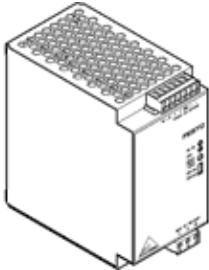

Data sheet

Feature	Value
Width	70 mm
Height	130 mm
Length	125 mm
Assembly position	Free convection
Primary supply	Single-phase
Input current	2,1 - 1,0 A
Nominal output voltage DC	30.1 V
Nominal output current	4.8 A
Input voltage range AC	100 ... 240 V
Power failure buffering	20 ms
Line frequency	45 ... 65 Hz
CE symbol (see declaration of conformity)	according to EU-EMV guideline according to EU low voltage guideline
Storage temperature	-40 ... 85 °C
Relative air humidity	95%
Protection class	IP20
Ambient temperature	-25 ... 70 °C
Authorization	C-Tick c UL us - Listed (OL)
Product weight	900 g
Mounting type	with top-hat rail
Materials note	Contains PWIS substances