


# Multi-pin socket connector NECA-S1G9-P9-MP2

Part number: 548720

FESTO

für Druckaufbau- und Entlüftungsventil MS6-SV erforderlich.

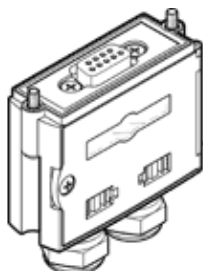

## Data sheet

Feature	Value
Width	20 mm
Height	62 mm
Length	61 mm
Permissible cable diameter	5 ... 10 mm
Operating voltage range DC	21.6 ... 26.4 V
Nominal operating voltage DC	24 V
Permissible current load	1 A
Corrosion resistance classification CRC	2
Storage temperature	-20 ... 70 °C
Relative air humidity	95% non-condensing
Protection class	IP65 to IEC 60529
Ambient temperature	0 ... 50 °C
Product weight	60 g
Terminal cross-section	0.34 ... 1 mm <sup>2</sup>
Hinweis zum Anschlussquerschnitt	0,34-0,5 mm <sup>2</sup> mit Aderendhülse
Electrical connection	9-polig / 9-polig Sub-D / Schraubklemme
Mounting type	with through hole
Materials information for locknut	Brass
Materials information for seals	NBR
Materials information, housing	PA-reinforced
Screw material data	Steel