


# Electrical interface

## VABE-S6-1LF-C-A4-E

Part number: 549042

FESTO

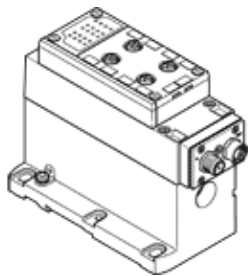

### Data sheet

Feature	Value
Assembly position	Any
Fieldbus interface	Socket M12x1/4-pin Plug, M12x, 4-pin
Max. number of solenoid coils	4
Number of slaves per device	1
Maximum number of outputs	4
Maximum number of inputs	4
Nominal operating voltage DC	24 V
Permissible voltage fluctuation	+/- 10 %
CE symbol (see declaration of conformity)	according to EU-EMV guideline according to EU low voltage guideline
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Storage temperature	-20 ... 60 °C
Relative air humidity	0 - 90 %
Protection class	IP65
Ambient temperature	-5 ... 50 °C
Product weight	850 g
Electrical connection	Fieldbus via CPX
Addressing range	1 ... 31 (0) Adjustment via AS interface addressing device
Electrical isolation, fieldbus interface	Optocoupler
Materials note	Conforms to RoHS
Material seals	NBR PUR
Material housing	Aluminum die cast PA