


# Multi-pin node VABE-S6-LT-C-S10-R5

Part number: 549047

FESTO

For valve manifolds VTSA and VTSA-F.

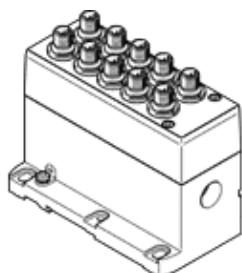

## Data sheet

Feature	Value
Assembly position	Any
Max. number of valve positions	10 with bistable valves 20 with monostable valves
Max. residual current	10 A
Nominal operating voltage DC	24 V
Permissible voltage fluctuation	+/- 10 %
Corrosion resistance classification CRC	0 - No corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Protection class	IP65 NEMA 4
Ambient temperature	-5 ... 50 °C
Product weight	790 g
Number of electrical connections	10
Electrical connection	Multi-pin plug 5-pin M12 Plug
Material cover	PA
Material housing	Aluminum die cast