

 

Socket connector MSSD-N

Part number: 550067

★ Core product range

For MD-2/2-... and MH-2/2-... solenoid coils

FESTO

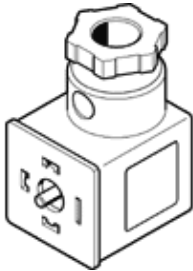

Data sheet

Feature	Value
Based on the standard	EN 175301-803
Cable outlet	Angled
Product weight	30 g
Electrical connection 1, design	Angular
Electrical connection 1, connection type	Plug socket
Electrical connection 1, connection technology	Plug pattern type A to EN 175301-803
Electrical connection 1, number of pins/wires	3
Electrical connection 1, type of mounting	On solenoid valve with M3 central screw
Electrical connection 2, connection technology	Screwed terminal
Operating voltage range DC	0 ... 24 V
Operating voltage range AC	0 ... 250 V
Acceptable current load at 40°C	16 A
Cable gland connection	M20x1,5
Cable diameter	8 ... 10 mm
Nominal conductor cross-section	1.5 mm ²
Protection class	IP65
Note on degree of protection	in assembled condition
Ambient temperature	-25 ... 80 °C
PWIS conformity	VDMA24364 zone III
Materials note	Conforms to RoHS
Material housing	PA-reinforced
Housing color	Black
Material screws	Steel
Material seals	VMQ